

MLFB-Ordering data 6SL3000-0CE35-1AA0

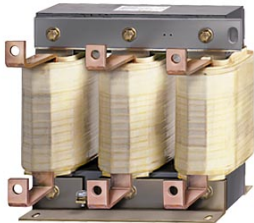


Figure similar

Client order no. :
Order no. :
Offer no. :
Remarks :

Item no. :
Consignment no. :
Project :

Rated data		Connections	
Input		Line side	
Number of phases	3 AC	Version	Flange connection for cable lug M14
Line voltage	380 ... 480 V		
Output		Load side	
Rated current	508.0 A	Version	Flange connection for cable lug M14
Mechanical data			
Dimensions		PE connection	
Width	300.0 mm (11.8 in)	Version	M8 Screw
Height	269.0 mm (10.6 in)		
Depth	212.5 mm (8.4 in)	Standards	
Degree of protection	IP00	Compliance with standards	cURus
Net weight	38.0 kg (83.8 lb)		