

MLFB-Ordering data                      6SL3000-0CE32-8AA0

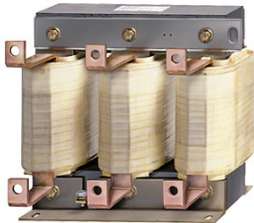


Figure similar

Client order no. :  
Order no. :  
Offer no. :  
Remarks :

Item no. :  
Consignment no. :  
Project :

Rated data		Connections	
Input		Line side	
Number of phases	3 AC	Version	Flange connection for cable lug M10
Line voltage	380 ... 480 V		
Output		Load side	
Rated current	278.0 A	Version	Flange connection for cable lug M10
Mechanical data			
Dimensions		PE connection	
Width	270.0 mm (10.6 in)	Version	M8 Screw
Height	248.0 mm (9.8 in)		
Depth	200.0 mm (7.9 in)	Standards	
Degree of protection	IP00	Compliance with standards	cURus
Net weight	26.0 kg (57.3 lb)		