

MLFB-Ordering data 6SL3000-0CE33-3AA0

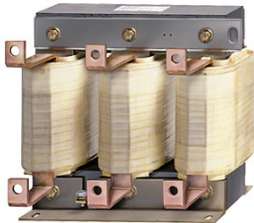


Figure similar

Client order no. :
Order no. :
Offer no. :
Remarks :

Item no. :
Consignment no. :
Project :

| Rated data | | Connections | |
|----------------------|--------------------|---------------------------|-------------------------------------|
| Input | | Line side | |
| Number of phases | 3 AC | Version | Flange connection for cable lug M10 |
| Line voltage | 380 ... 480 V | | |
| Output | | Load side | |
| Rated current | 331.0 A | Version | Flange connection for cable lug M10 |
| Mechanical data | | | |
| Dimensions | | PE connection | |
| Width | 270.0 mm (10.6 in) | Version | M8 Screw |
| Height | 248.0 mm (9.8 in) | Standards | |
| Depth | 200.0 mm (7.9 in) | | |
| Degree of protection | IP00 | | |
| Net weight | 27.8 kg (61.3 lb) | Compliance with standards | cURus |