

MLFB-Ordering data 6SL3000-0CE33-3AA0

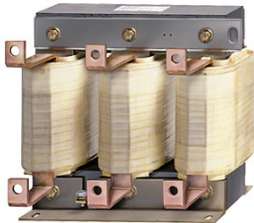


Figure similar

Client order no. :
Order no. :
Offer no. :
Remarks :

Item no. :
Consignment no. :
Project :

Rated data		Connections	
Input		Line side	
Number of phases	3 AC	Version	Flange connection for cable lug M10
Line voltage	380 ... 480 V		
Output		Load side	
Rated current	331.0 A	Version	Flange connection for cable lug M10
Mechanical data			
Dimensions		PE connection	
Width	270.0 mm (10.6 in)	Version	M8 Screw
Height	248.0 mm (9.8 in)	Standards	
Depth	200.0 mm (7.9 in)		
Degree of protection	IP00		
Net weight	27.8 kg (61.3 lb)	Compliance with standards	cURus