

MLFB-Ordering data 6SL3000-0CH31-1AA0

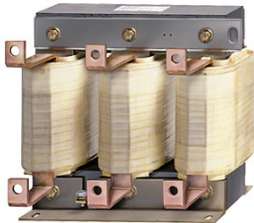


Figure similar

Client order no. :
Order no. :
Offer no. :
Remarks :

Item no. :
Consignment no. :
Project :

Rated data		Connections	
Input		Line side	
Number of phases	3 AC	Version	1 x hole for M10
Line voltage	660 ... 690 V		
Output		Load side	
Rated current	107.0 A	Version	1 x hole for M10
Mechanical data			
Dimensions		PE connection	
Width	270.0 mm (10.6 in)	Version	M6 screw
Height	248.0 mm (9.8 in)	Standards	
Depth	200.0 mm (7.9 in)		
Degree of protection	IP00		
Net weight	24.4 kg (53.8 lb)	Compliance with standards	cURus