

Data sheet for Output reactor

Article No. : 6SL3000-2AH31-0AA0

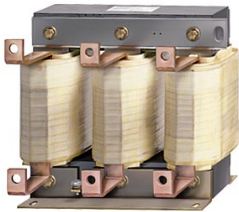


Figure similar

Client order no. :
Order no. :
Offer no. :
Remarks :

Item no. :
Consignment no. :
Project :

| Rated data | |
|----------------------|-------------------|
| Rated current | 100.00 A |
| Power loss | 0.300 kW |
| Mechanical data | |
| Degree of protection | IP00 |
| Net weight | 25 kg (55.12 lb) |
| Dimensions | |
| Width | 270 mm (10.63 in) |
| Height | 248 mm (9.76 in) |
| Depth | 200 mm (7.87 in) |

| Connections | |
|-------------------------|------------------------------|
| Power connection motor | |
| Version | flat connector for M10 screw |
| Max. motor cable length | |
| Shielded | 300 m (984.25 ft) |
| Unshielded | 450 m (1,476.38 ft) |
| PE connection | |
| Version | M6 screw |