

Data sheet for Output reactor

Article No. : 6SL3000-2BE32-1AA0

Client order no. :
Order no. :
Offer no. :
Remarks :

Item no. :
Consignment no. :
Project :

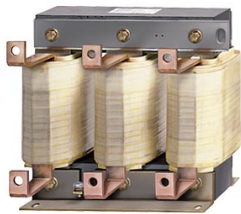


Figure similar

| Rated data | |
|---------------|----------|
| Rated current | 210.00 A |
| Power loss | 0.486 kW |

| Mechanical data | |
|----------------------|-------------------|
| Degree of protection | IP00 |
| Net weight | 60 kg (132.28 lb) |

| Dimensions | |
|------------|-------------------|
| Width | 300 mm (11.81 in) |
| Height | 285 mm (11.22 in) |
| Depth | 257 mm (10.12 in) |

| Connections | |
|-------------------------------|-------------------------------------|
| Power connection Power Module | |
| Version | flat connector for cable lug M10 |
| Power connection motor | |
| Version | Flange connection for cable lug M10 |
| Max. motor cable length | |
| 3 AC 380 V -10 % ... 400 V | |
| Shielded | 300 m |
| Unshielded | 450 m |
| 3 AC 401 V ... 480 V +10 % | |
| Shielded | 300 m |
| Unshielded | 450 m |
| PE connection | |
| Version | M8 Screw |